




PRODUCT DESCRIPTION

Two tone frames of Black or White with internal Gold frames provides a neoclassical approach to the squared coach lantern. The sconces jut out from the wall on well-defined trusses that add a contemporary element. Delivering classic design that suits most exteriors, this collection adds interest in the interior contrasting frame of Gold that secures clear glass panes to diffuse the lamp within.

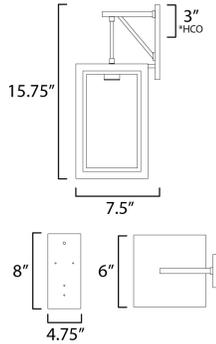

*Height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 6" W x 15.75" H x 7.5" Ext
 BACK PLATE : 4.75" W x 8" H x 3" HCO
 HANGING WEIGHT : 2.2 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total
 BULB INCLUDED : (Not Included)

FINISHES OPTION



GLASS

Clear CL

MATERIAL

Aluminum, Glass

RATINGS

Wet Location



ADDITIONAL

INSTALL UP/DOWN: Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com