




PRODUCT DESCRIPTION

Two tone frames of Black or White with internal Gold frames provides a neoclassical approach to the squared coach lantern. The sconces jut out from the wall on well-defined trusses that add a contemporary element. Delivering classic design that suits most exteriors, this collection adds interest in the interior contrasting frame of Gold that secures clear glass panes to diffuse the lamp within.

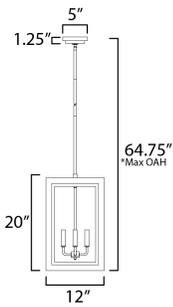

*max overall height

MEASUREMENTS

- DIMENSION : 12" L x 12" W x 20" H
- MAX OAH : 64.75" OAH
- CANOPY : 5" W x 1.25" H x 5" L
- HANGING WEIGHT : 7.7 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 4 x 40W Incandescent E12 Candelabra , 160W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Y

FINISHES OPTION

-  Black / Gold
-  White/Gold

GLASS

Clear CL

MATERIAL

Aluminum, Glass

RATINGS

cETLus
Damp Location



ADDITIONAL

OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com