




PRODUCT DESCRIPTION

Squared columns in Matte Black finish tower above the cylindrical glass shade rated for outdoor applications. A rectangular hook detail carries the square form through to the backplate. A modern interpretation of a bell tower, these outdoor pendants and sconces are a cleaned up, transitional look for exteriors.

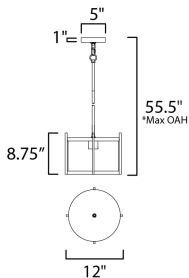

*max overall height

MEASUREMENTS

DIMENSION : 12" L x 12" W x 8.75" H
MAX OAH : 55.5" OAH
HANGING WEIGHT : 8.75 lb

LAMPING

INPUT VOLTAGE : 120V
BULB : 1 x 60W Incandescent E26 Medium , 60W Total
BULB INCLUDED : (Not Included)
DIMMABLE : Y

FINISHES OPTION

 Black

GLASS

Clear CL

MATERIAL

Aluminum, Glass

RATINGS

cETLus
Damp Location



ADDITIONAL

OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com