




PRODUCT DESCRIPTION

Squared columns in Matte Black finish tower above the cylindrical glass shade rated for outdoor applications. A rectangular hook detail carries the square form through to the backplate. A modern interpretation of a bell tower, these outdoor pendants and sconces are a cleaned up, transitional look for exteriors.

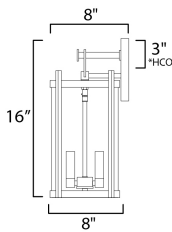

*height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 8" W x 16" H x 8" Ext
BACK PLATE : 4.75" W x 6.25" H x 3" HCO
HANGING WEIGHT : 5.72 lb

LAMPING

INPUT VOLTAGE : 120V
BULB : 2 x 40W Incandescent E12 Candelabra , 80W Total
BULB INCLUDED : (Not Included)
DIMMABLE : Y
LIGHTING_DIRECTION : Up

FINISHES OPTION

Black

GLASS

Clear CL

MATERIAL

Aluminum, Glass

RATINGS

cETLus
Wet Location



ADDITIONAL

INSTALL UP/DOWN: Up
RATED LIFE 2500 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com