




PRODUCT DESCRIPTION

An elongated rectangular shaped design that is both minimalist and industrial. Die cast frames of Dark Bronze support Clear glass panels that provide an unobstructed view of the lantern's interior. Customize with your choice of lamps from vintage to tubular.

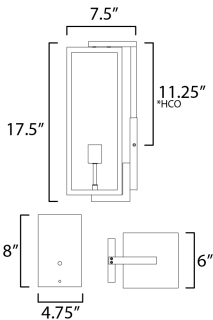

\*Height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 6" W x 17.5" H x 7.5" Ext  
BACK PLATE : 4.75" W x 8" H x 11.25" HCO  
HANGING WEIGHT : 6.38 lb

LAMPING

INPUT VOLTAGE : 120V  
BULB : 1 x 60W Incandescent E26 Medium , 60W Total  
BULB INCLUDED : (Not Included)  
DIMMABLE :

FINISHES OPTION

 Dark Bronze

GLASS

Clear CL

MATERIAL

Aluminum, Glass

RATINGS

cETLus  
Wet Location



ADDITIONAL

INSTALL UP/DOWN: Up  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269  
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com