




PRODUCT DESCRIPTION

A dual framed structure creates dimension on these outdoor lighting fixtures that is both contemporary and transitional. The construction consists of two frames of square tubing and squared components. The inner frame's Clear Seedy glass reduces glare from the light and appears dirt-free for longer periods. This is a comprehensive collection to brighten all areas of your outdoor space, available in various sized sconces as well as hanging and post configurations.

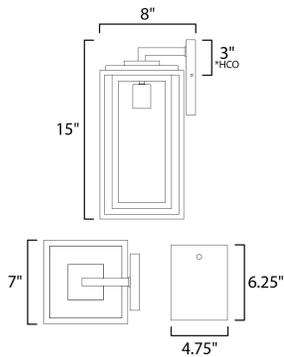

*height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 7" W x 15" H x 8" Ext
 BACK PLATE : 4.75" W x 6.25" H x 3" HCO
 HANGING WEIGHT : 4.5 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y

FINISHES OPTION

 Black

GLASS

Seedy CD

MATERIAL

Aluminum, Glass

RATINGS

cETLus
 Wet Location



ADDITIONAL

INSTALL UP/DOWN: Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com