




PRODUCT DESCRIPTION

Hand formed glass petals suspend from a tiered frame of Polished Chrome. The glass is transparent yet cloudy, softly diffusing the light while creating a clean and crisp design.

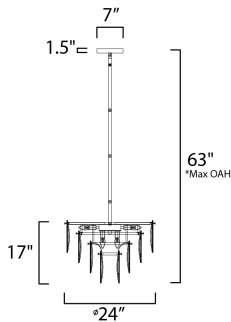

*max overall height

MEASUREMENTS

- DIMENSION : 24" L x 24" W x 17" H
- MAX OAH : 63" OAH
- CANOPY : 7" W x 1.5" H x 7" L
- HANGING WEIGHT : 45.1 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 9 x 40W Incandescent E12 Candelabra , 360W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Yes

FINISHES OPTION

- White / Polished Chrome

GLASS

- Clear CL

MATERIAL

- Steel, Glass

RATINGS

- cETLus
- Dry Location



ADDITIONAL

- OPERATING TEMPERATURE: -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, GA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com