




PRODUCT DESCRIPTION

Hand-formed glass petals of Clear and Champagne-tint suspend from a tiered frame of gold and accented with petals of solid metal finished in Gold Leaf. Numerous candelabra sockets are strategically placed within the fixture to create glimmer and elegance to this majestic collection.

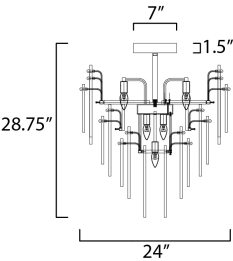

MEASUREMENTS

- DIMENSION : 24" L x 24" W x 28.75" H
- MAX OAH : 28.75" OAH
- CANOPY : 7" W x 1.5" H x 7" L
- HANGING WEIGHT : 63.8 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 1 x 40W Incandescent E12 Candelabra , 400W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Yes

FINISHES OPTION

- Gold Leaf

GLASS

Clear and Champagne CLCMP

MATERIAL

Steel, Glass

RATINGS

cETLus
Damp Location



ADDITIONAL

OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, GA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com