




**PRODUCT DESCRIPTION**

Hand-formed glass petals of Clear and Champagne-tint suspend from a tiered frame of gold and accented with petals of solid metal finished in Gold Leaf. Numerous candelabra sockets are strategically placed within the fixture to create glimmer and elegance to this majestic collection.

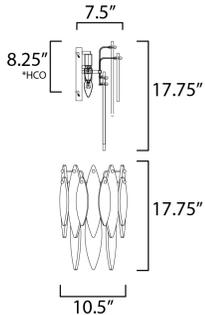

\*height from center of outlet to the top of the fixture

**MEASUREMENTS**

DIMENSION : 10.5" L x 10.5" W x 17.75" H x 7.5" Ext  
 MAX OAH : 7" W x 8.75" H  
 HANGING WEIGHT : 10.12 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 3 x 40W Incandescent E12 Candelabra , 120W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Yes  
 LIGHTING\_DIRECTION : Down

**FINISHES OPTION**

 Gold Leaf

**GLASS**

Clear and Champagne CLCMP

**MATERIAL**

Steel, Glass

**RATINGS**

cETLus  
 Damp Location



**ADDITIONAL**

INSTALL UP/DOWN: Down  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
**EASTERN DISTRIBUTION CENTER**  
 4200 SHIRLEY DR. | ATLANTA, GA 30336  
 P. 626.956.4200 | F. 626.956.4225 | maximlighting.com