



**PRODUCT DESCRIPTION**

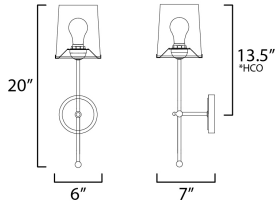
Satin White shades taper in a classic fabric shade shape and rest on elegantly thin frames of Satin Brass or Satin Nickel. They are supported secured by a mostly concealed structure with coordinating semicircular tabs that complement the spherical joints of the frame. The modern design details and updated shade materials refresh the outlook of a timeless chandelier though its use of thoughtful features.

**MEASUREMENTS**

DIMENSION : 6" W x 20" H x 7" Ext  
 MAX OAH : 4.75" W x 4.75" H  
 HANGING WEIGHT : 1.9 lb



**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Y



\*height to center of outlet to the top of the fixture

**FINISHES OPTION**

-  Satin Brass
-  Satin Nickel

**GLASS**

White WT

**MATERIAL**

Steel, Glass

**RATINGS**

cETLus  
 Damp Location



**ADDITIONAL**

INSTALL UP/DOWN: Up  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com