




PRODUCT DESCRIPTION

Satin White shades taper in a classic fabric shade shape and rest on elegantly thin frames of Satin Brass or Satin Nickel. They are supported secured by a mostly concealed structure with coordinating semicircular tabs that complement the spherical joints of the frame. The modern design details and updated shade materials refresh the outlook of a timeless chandelier though its use of thoughtful features.

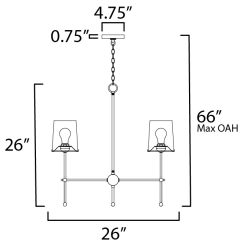

*max overall height

MEASUREMENTS

- DIMENSION : 26" L x 26" W x 26" H
- MAX OAH : 66" OAH
- CANOPY : 4.75" W x 0.75" H x 4.75" L
- HANGING WEIGHT : 6.86 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 4 x 60W Incandescent E26 Medium , 240W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Y

FINISHES OPTION

- Satin Brass
- Satin Nickel

GLASS

White WT

MATERIAL

Steel, Glass

RATINGS

cETLus
Dry Location



ADDITIONAL

OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com