




**PRODUCT DESCRIPTION**

Coastally inspired, the wide brimmed aluminum spun shade on this series of outdoor rated sconces, pendants, and flush mounts features a tiered shade design. The ringed separation features a filigree of oval cut outs, whereby a single lamp illuminates the Satin White glass supporting it. The resulting light is dispersed both above and below the spun shade as well as through the patterned filigree. Both modern and classic homes can appreciate this classic design reimaged. The series is available either in Matte Black or a striking Two-Tone Black with Antique Brass.

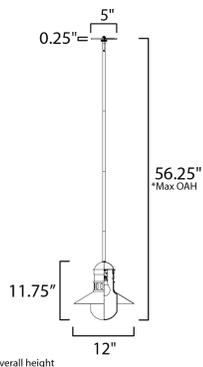

**MEASUREMENTS**

- DIMENSION : 12" L x 12" W x 11.75" H
- MAX OAH : 56.25" OAH
- CANOPY : 5" W x 0.25" H x 5" L
- HANGING WEIGHT : 4.34 lb

**LAMPING**

- INPUT VOLTAGE : 120V
- BULB : 1 x 60W Incandescent E26 Medium , 60W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Y

**FINISHES OPTION**

-  Black
-  Black / Antique Brass

**GLASS**

Satin White SW

**MATERIAL**

Aluminum, Glass

**RATINGS**

cETLus  
Wet Location



**ADDITIONAL**

OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com