


PRODUCT DESCRIPTION

Rectangular Beveled Crystals are suspended from a channel of Polished Chrome. The crystal sparkles and shimmers when illuminated by the LED source encased in the channel. This contemporary will add elegance to a wide variety of room decors.

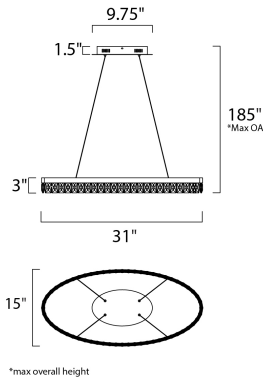

MEASUREMENTS

DIMENSION : 31" L x 15" W x 3" H
 MAX OAH : 185" OAH
 CANOPY : 5.25" W x 1.75" H x 9.75" L
 HANGING WEIGHT : 7.94 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 2,900 Rated (2,000 Del.)
 BULB : 1 x 42W LED PCB Integrated , 42W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE : Triac CL
 CRI : 90+ CRI
 COLOR_TEMP : 3000K

FINISHES OPTION



GLASS

Beveled Crystal BC

MATERIAL

Stainless Steel, Steel, Glass

RATINGS

cETLus
 Dry Location



ADDITIONAL

ADJUSTABLE
 RATED LIFE 25000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
 4200 SHIRLEY DR. | ATLANTA, GA 30336
 P. 626.956.4200 | F. 626.956.4225 | maximlighting.com