



**PRODUCT DESCRIPTION**

The composition of Clear glass rods are elegantly supported by thin radial arms of staggered lengths to create an iridescent motif that is truly Divine. Finished in Polished Nickel or Heritage Brass, the simplicity of this design delivers a crisp lighting fixture that works in a multitude of interior aesthetics from contemporary to traditional.

**FINISHES OPTION**

-  Heritage
-  Polished Nickel

**GLASS**

Clear CL

**MATERIAL**

Steel, Glass

**RATINGS**

cULus  
Dry Location



**ADDITIONAL**


ADJUSTABLE  
SLOPE: 90  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

**MEASUREMENTS**

- DIMENSION : 28.5" L x 28.5" W x 25.5" H
- MAX OAH : 59" OAH
- CANOPY : 5" W x 0.75" H x 5" L
- HANGING WEIGHT : 26.4 lb

**LAMPING**

- INPUT VOLTAGE : 120V
- BULB : 8 x 60W Incandescent E12 Candelabra , 480W Total
- BULB INCLUDED : (Not Included)

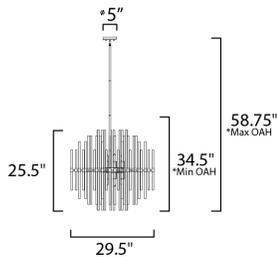

\*max overall height

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com