




PRODUCT DESCRIPTION

The composition of Clear glass rods are elegantly supported by thin radial arms of staggered lengths to create an iridescent motif that is truly Divine. Finished in Polished Nickel or Heritage Brass, the simplicity of this design delivers a crisp lighting fixture that works in a multitude of interior aesthetics from contemporary to traditional.

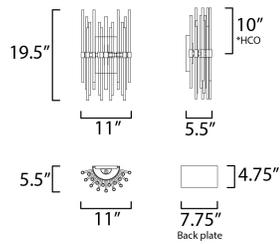

MEASUREMENTS

DIMENSION : 11" W x 19.5" H x 5.5" Ext
 MAX OAH : 58.5" OAH x 4.75" W x 7.75" H
 HANGING WEIGHT : 5.94 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 2 x 60W Incandescent E12 Candelabra , 120W Total
 BULB INCLUDED : (Not Included)
 LIGHTING_DIRECTION : Up/Down

FINISHES OPTION

-  Heritage
-  Polished Nickel

GLASS

Clear CL

MATERIAL

Steel, Glass

RATINGS

cULus
 Dry Location



ADDITIONAL

INSTALL UP/DOWN: Up
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

*height from center of outlet to the top of the fixture

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com