

PRODUCT DESCRIPTION

Piastra style glass diffuses integrated LED to shimmer radiantly. Suspended on a Black frame with Gold Leaf accents, this perfect blend of contemporary and traditional design adds glamour to a broad spectrum of design aesthetics.

FINISHES OPTION

 Black / Gold Leaf

GLASS

Crystalline CY

MATERIAL

Steel, Aluminum, Glass

RATINGS

cETLus
Dry Location



ADDITIONAL


ADJUSTABLE
SLOPE: 90
RATED LIFE 20000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

MEASUREMENTS

DIMENSION : 26.75" L x 26.75" W x 12.25" H
MAX OAH : 60.5" OAH
CANOPY : 7" W x 1.75" H x 7" L
HANGING WEIGHT : 22.71 lb

LAMPING

INPUT VOLTAGE : 120-277V
LUMENS : 3,535 Rated (2,430 Del.)
BULB : 9 x 6W LED PCB Integrated , 54W Total
BULB INCLUDED : (Integrated)
DIMMABLE : Triac CL
CRI : 90 CRI
COLOR_TEMP : 3000K

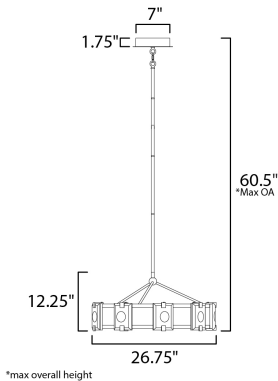

*max overall height

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com