

**PRODUCT DESCRIPTION**


Piastra style glass diffuses integrated LED to shimmer radiantly. Suspended on a Black frame with Gold Leaf accents, this perfect blend of contemporary and traditional design adds glamour to a broad spectrum of design aesthetics.

**MEASUREMENTS**

DIMENSION : 34.75" L x 34.75" W x 14" H  
 MAX OAH : 62.25" OAH  
 CANOPY : 7" W x 1.75" H x 7" L  
 HANGING WEIGHT : 29.39 lb

**LAMPING**

INPUT VOLTAGE : 120-277V  
 LUMENS : 4,060 Rated (2,830 Del.)  
 BULB : 12 x 6W LED PCB Integrated , 72W Total  
 BULB INCLUDED : (Integrated)  
 DIMMABLE : Triac CL  
 CRI : 90 CRI  
 COLOR\_TEMP : 3000K

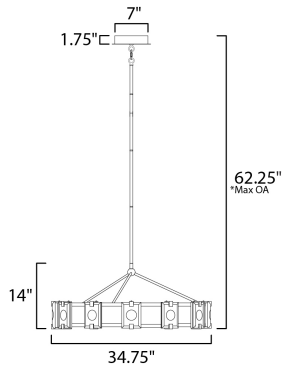

**FINISHES OPTION**

 Black / Gold Leaf

**GLASS**

Crystalline CY

**MATERIAL**

Steel, Aluminum, Glass

**RATINGS**

cETLus  
 Dry Location



**ADDITIONAL**

ADJUSTABLE  
 SLOPE: 90  
 RATED LIFE 20000 Hours  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
**EASTERN DISTRIBUTION CENTER**  
 4200 SHIRLEY DR. | ATLANTA, GA 30336  
 P. 626.956.4200 | F. 626.956.4225 | maximlighting.com