




PRODUCT DESCRIPTION

Piastra style glass diffuses integrated LED to shimmer radiantly. Suspended on a Black frame with Gold Leaf accents, this perfect blend of contemporary and traditional design adds glamour to a broad spectrum of design aesthetics.

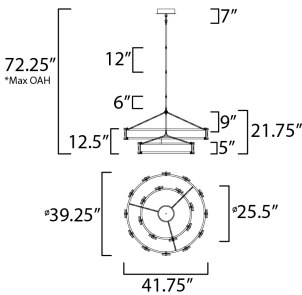

*max overall height

MEASUREMENTS

DIMENSION : 41.75" L x 41.75" W x 21.75" H
MAX OAH : 72.25" OAH
CANOPY : 7.75" W x 1.5" H x 7.75" L
HANGING WEIGHT : 43 lb

LAMPING

INPUT VOLTAGE : 120-277V
LUMENS : 5,300 Rated (4,000 Del.)
BULB : 2 x 3.8W LED PCB Integrated , 76W Total
BULB INCLUDED : (Integrated)
DIMMABLE : Yes
CRI : 90 CRI
COLOR_TEMP : 3000K

FINISHES OPTION

 Black / Gold Leaf

GLASS

Crystalline CY

MATERIAL

Steel, Glass

RATINGS

cETLus
Dry Location



ADDITIONAL

SLOPE: 90
RATED LIFE 20000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, GA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com