




PRODUCT DESCRIPTION

Contemporary Industrial design is met with the Kinetic series transforming mechanical parts into beautiful metal components finished in Dark Satin Nickel. Wire cord is run along a truss like structure separated by transformer-like castings. Large Clear glass globes are suspended from brackets with recessed LED illumination coming from decorative heat sinks.

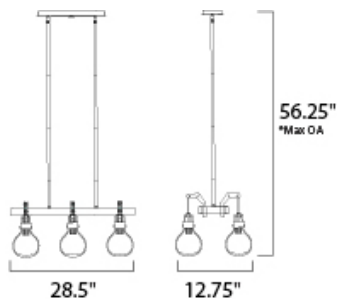

*max overall height of fixture

MEASUREMENTS

DIMENSION : 28.25" L x 17.5" W x 14.25" H
 MAX OAH : 57" OAH
 CANOPY : 5" W x 0.75" H x 15.75" L
 HANGING WEIGHT : 26.45 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 3,360 Rated
 BULB : 6 x 6W LED AC Integrated , 36W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE : Triac CL
 CRI : 90+ CRI
 COLOR_TEMP : 3000K

FINISHES OPTION

 Dark Satin Nickel

GLASS

Clear CL

MATERIAL

Steel, Aluminum, Glass

RATINGS

cETLus
 Dry Location



ADDITIONAL

ADJUSTABLE
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, GA 91746
EASTERN DISTRIBUTION CENTER
 4200 SHIRLEY DR. | ATLANTA, GA 30336
 P. 626.956.4200 | F. 626.956.4225 | maximlighting.com