



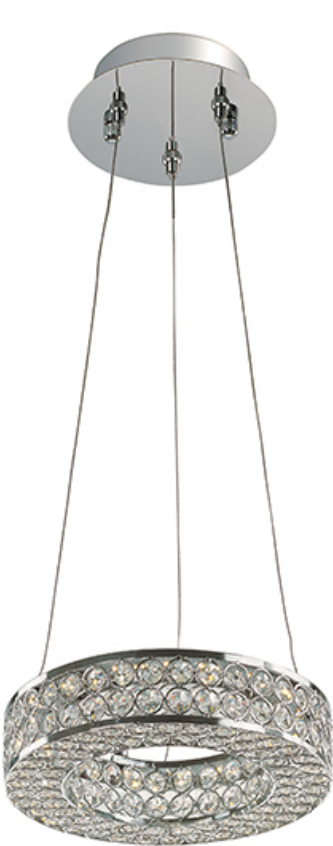

PRODUCT DESCRIPTION

Frames of metal rings encased with Beveled Crystal Jewels, are finished in Polished Chrome. Suspended by cables as if floating in air, these rings cast rainbows of light when illuminated by the Integrated LED.

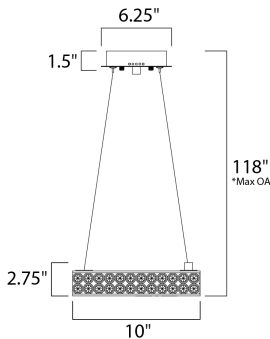

*max overall height

MEASUREMENTS

DIMENSION : 10" L x 10" W x 2.75" H
MAX OAH : 118" OAH
CANOPY : 6.25" W x 1.5" H x 6.25" L
HANGING WEIGHT : 3.66 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 420 Rated
BULB : 1 x 6W LED PCB Integrated , 6W Total
BULB INCLUDED : (Integrated)
DIMMABLE : Triac CL
CRI : 80+ CRI
COLOR_TEMP : 3000K

FINISHES OPTION

Polished Chrome

GLASS

Beveled Crystal BC

MATERIAL

Steel, Crystal

RATINGS

cETLus
Dry Location



ADDITIONAL

RATED LIFE 40000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, GA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com