




PRODUCT DESCRIPTION

Frames of metal rings encased with Beveled Crystal Jewels, are finished in Polished Chrome. Suspended by cables as if floating in air, these rings cast rainbows of light when illuminated by the Integrated LED.

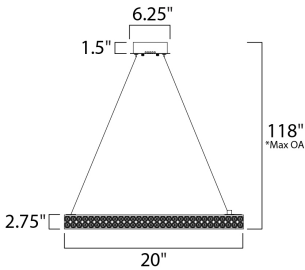

\*max overall height

MEASUREMENTS

- DIMENSION : 20" L x 20" W x 2.75" H
- MAX OAH : 118" OAH
- CANOPY : 6.25" W x 1.5" H x 6.25" L
- HANGING WEIGHT : 6.61 lb

LAMPING

- INPUT VOLTAGE : 120V
- LUMENS : 630 Rated
- BULB : 1 x 9W LED PCB Integrated , 9W Total
- BULB INCLUDED : (Integrated)
- DIMMABLE : Triac CL
- CRI : 80+ CRI
- COLOR\_TEMP : 3000K

FINISHES OPTION

- Polished Chrome

GLASS

Beveled Crystal BC

MATERIAL

Steel, Crystal

RATINGS

cETLus  
Dry Location



ADDITIONAL

RATED LIFE 40000 Hours  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, GA 91746  
EASTERN DISTRIBUTION CENTER  
4200 SHIRLEY DR. | ATLANTA, GA 30336  
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com