




PRODUCT DESCRIPTION

Frames of metal rings encased with Beveled Crystal Jewels, are finished in Polished Chrome. Suspended by cables as if floating in air, these rings cast rainbows of light when illuminated by the Integrated LED.

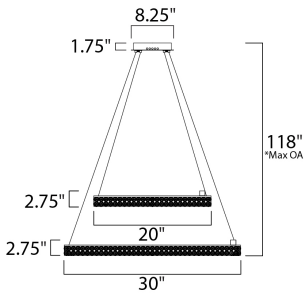

*max overall height

MEASUREMENTS

- DIMENSION : 30" L x 30" W x 2.75" H
- MAX OAH : 118" OAH
- CANOPY : 8.25" W x 1.75" H x 8.25" L
- HANGING WEIGHT : 16.71 lb

LAMPING

- INPUT VOLTAGE : 120V
- LUMENS : 1,680 Rated
- BULB : 1 x 24W LED PCB Integrated , 24W Total
- BULB INCLUDED : (Integrated)
- DIMMABLE : Triac CL
- CRI : 80+ CRI
- COLOR_TEMP : 3000K
- LIGHTING_DIRECTION : Down

FINISHES OPTION

- Polished Chrome

GLASS

- Beveled Crystal BC

MATERIAL

- Steel, Crystal

RATINGS

- cETLus
- Dry Location



ADDITIONAL

- INSTALL UP/DOWN: Down
- RATED LIFE 40000 Hours
- OPERATING TEMPERATURE: -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, GA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com