




PRODUCT DESCRIPTION

Dew collection's drops of Chrome plated glass are randomly displayed as if floating in air. The metal pan, finished in Polished Chrome, comes with halogen bulbs. The Dew collection is also available with long life, energy efficient LED light in the Dew LED collection.

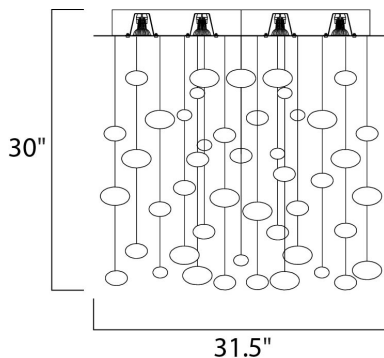

MEASUREMENTS

DIMENSION : 31.5" W x 30" H
HANGING WEIGHT : 28.88 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 15,300 Rated
BULB : 9 x 35W Halogen GU10 MR16 , 315W Total
BULB INCLUDED : (Included)
DIMMABLE : Yes
COLOR_TEMP : 2900K

FINISHES OPTION

 Polished Chrome

GLASS

Polish Chrome PC

MATERIAL

Steel, Plated Glass

RATINGS

cETLus
Dry Location



ADDITIONAL

RATED LIFE 2000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com