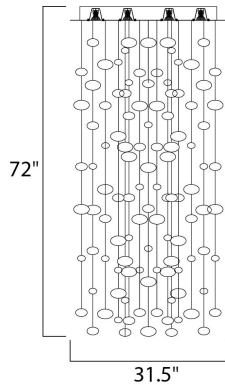


**PRODUCT DESCRIPTION**

Dew collection's drops of Chrome plated glass are randomly displayed as if floating in air. The metal pan, finished in Polished Chrome, comes with halogen bulbs. The Dew collection is also available with long life, energy efficient LED light in the Dew LED collection.

**MEASUREMENTS**

DIMENSION : 31.5" W x 72" H  
HANGING WEIGHT : 33.38 lb

**LAMPING**

INPUT VOLTAGE : 120V  
LUMENS : 15,300 Rated  
BULB : 9 x 50W Halogen GU10 MR16 , 450W Total  
BULB INCLUDED : (Included)  
DIMMABLE : Yes  
COLOR\_TEMP : 2900K

**FINISHES OPTION**

 Polished Chrome

**GLASS**

Polish Chrome PC

**MATERIAL**

Steel, Plated Glass

**RATINGS**

cETLus  
Dry Location

**ADDITIONAL**

RATED LIFE 2000 Hours  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

**EASTERN DISTRIBUTION CENTER**  
4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com