



PRODUCT DESCRIPTION


Stately outdoor sconces reference classic lantern shapes and are constructed of Maxim's proprietary Vivex composite, a robust weather-resistant materials guaranteed to withstand harsh weather climates. Available in several sizes and illuminated with clusters of candle sockets, this is a timeless design built to last.

MEASUREMENTS

DIMENSION : 7.75" W x 14.5" H x 8.75" Ext
 BACK PLATE : 4.75" W x 8" H x 7" HCO
 HANGING WEIGHT : 4.14 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y

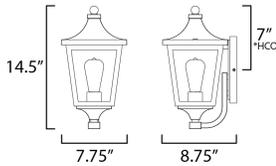

*Height from center of outlet to the top of the fixture

FINISHES OPTION

 Black

GLASS

Clear CL

MATERIAL

EPMM Vivex, Glass

RATINGS

cETLus
 Wet Location



ADDITIONAL

INSTALL UP/DOWN: Up
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com