




PRODUCT DESCRIPTION

Stately outdoor sconces reference classic lantern shapes and are constructed of Maxim's proprietary Vivex composite, a robust weather-resistant materials guaranteed to withstand harsh weather climates. Available in several sizes and illuminated with clusters of candle sockets, this is a timeless design built to last.

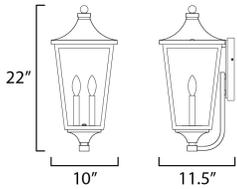

MEASUREMENTS

DIMENSION : 10" W x 22" H x 11.5" Ext
 BACK PLATE : 6.25" W x 9.5" H x 14" HCO
 HANGING WEIGHT : 8.69 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 2 x 40W Incandescent E12 Candelabra , 80W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y

FINISHES OPTION

 Black

GLASS

Clear CL

MATERIAL

EPMM Vivex, Glass

RATINGS

cETLus
 Wet Location



ADDITIONAL

INSTALL UP/DOWN: Up
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com