




PRODUCT DESCRIPTION

Using our proprietary Vivex material developed for use in harsh climates, the Nassau series presents Coastal styling, historical in design, made of an appropriately specified material for just this application. Available in your choice of solid Black or a cool combination of White with Black accents, the lanterns protect clusters of candelabras with clear glass panels. Add filament lamps to the lanterns to complete the look.

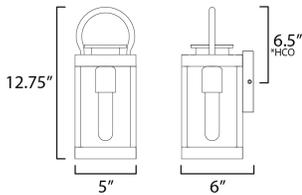

*Height from center of outlet to the top of the fixture

MEASUREMENTS

- DIMENSION : 5" W x 12.75" H x 6" Ext
- BACK PLATE : 5" W x 5" H x 6.5" HCO
- HANGING WEIGHT : 3.1 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 1 x 60W Incandescent E26 Medium , 60W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Y

FINISHES OPTION

- Black
- White / Black

GLASS

Clear CL

MATERIAL

EPMM Vivex, Glass

RATINGS

cETLus
Wet Location



ADDITIONAL

INSTALL UP/DOWN: Down
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com