




**PRODUCT DESCRIPTION**

Using our proprietary Vivex material developed for use in harsh climates, the Nassau series presents Coastal styling, historical in design, made of an appropriately specified material for just this application. Available in your choice of solid Black or a cool combination of White with Black accents, the lanterns protect clusters of candelabras with clear glass panels. Add filament lamps to the lanterns to complete the look.

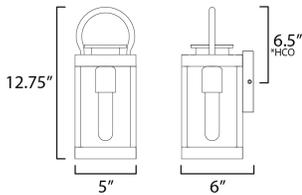

**MEASUREMENTS**

DIMENSION : 5" W x 12.75" H x 6" Ext  
 BACK PLATE : 5" W x 5" H x 6.5" HCO  
 HANGING WEIGHT : 3.1 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Y

\*Height from center of outlet to the top of the fixture

**FINISHES OPTION**



**GLASS**

Clear CL

**MATERIAL**

EPMM Vivex, Glass

**RATINGS**

cETLus  
 Wet Location



**ADDITIONAL**

INSTALL UP/DOWN: Down  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com