




**PRODUCT DESCRIPTION**

Clean glass cylinders and banded frames provide a transitional design between Coastal, Craftsman, and Modern styles. Clear glass protects the light sources, and the frames are coated in our protective Vivex composite, which is designed to handle harsher coastal conditions. An incredible value and simple design, the Clyde series is an easy selection for most exterior applications.

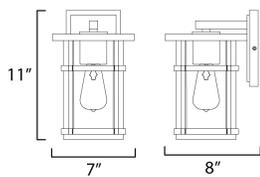

**MEASUREMENTS**

DIMENSION : 7" W x 11" H x 8" Ext  
 BACK PLATE : 4.75" W x 6.5" H x 7.75" HCO  
 HANGING WEIGHT : 2.55 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Y

**FINISHES OPTION**

 Black

**GLASS**

Clear CL

**MATERIAL**

EPMM Vivex, Glass

**RATINGS**

cETLus  
 Wet Location



**ADDITIONAL**

INSTALL UP/DOWN: Down  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com