



PRODUCT DESCRIPTION


Clean glass cylinders and banded frames provide a transitional design between Coastal, Craftsman, and Modern styles. Clear glass protects the light sources, and the frames are coated in our protective Vivex composite, which is designed to handle harsher coastal conditions. An incredible value and simple design, the Clyde series is an easy selection for most exterior applications.

MEASUREMENTS

DIMENSION : 9" W x 14" H x 10" Ext
 BACK PLATE : 4.75" W x 8" H x 10" HCO
 HANGING WEIGHT : 4.4 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y

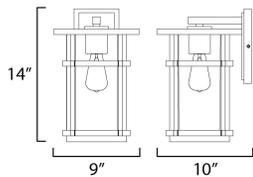

FINISHES OPTION

 Black

GLASS

Clear CL

MATERIAL

EPMM Vivex, Glass

RATINGS

cETLus
 Wet Location



ADDITIONAL

INSTALL UP/DOWN: Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com