




PRODUCT DESCRIPTION

Styled as a classic early American coach lantern, the Yorktown sconces offer an established exterior design aesthetic with the modern engineering to withstand the harshest climates. A crossing pattern of the material wraps clear glass panes that protects them and adds visual interest. Featured prominently on the back plate of these lanterns is a stainless-steel overlay in Antique Copper that evokes the historical reference embodied in the design and attractive contrast to the fixtures rated for wet locations.

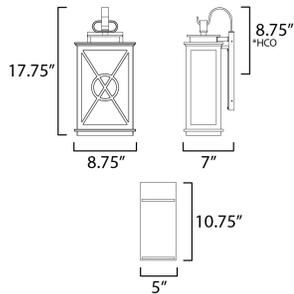

*Height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 8.75" W x 17.75" H x 7" Ext
 BACK PLATE : 4.9" W x 10.9" H x 8.75" HCO
 HANGING WEIGHT : 9.46 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y
 LIGHTING_DIRECTION : Down

FINISHES OPTION

Black/Aged Copper

GLASS

Clear CL

MATERIAL

Vivex EPMM,Glass

RATINGS

cETLus
 Wet Location



ADDITIONAL

INSTALL UP/DOWN: Vertical
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com