



PRODUCT DESCRIPTION


Tasteful details on this series of low-profile Vivex sconces and flush mounts adds a stylish touch to functional spaces. Finished in a two-tone Black and Gold combination, this Vivex series is engineered to withstand harsher climates adding fashionable flare to a necessary lighting element. The Gold rivet details at its corners are not just decorative, but structurally secure an outer shell that seals its internal LED housing from water intrusion. The applications of the flush mount and slim sconces provide dimensional convenience and accessibility for limited spaces or hallways regulated by ADA requirements.

MEASUREMENTS

DIMENSION : 5.5" W x 5.5" H x 3.25" Ext
 BACK PLATE : 4.75" W x 4.75" H x 2.75" HCO
 HANGING WEIGHT : 1.1 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 780 Rated (450 Del.)
 BULB : 1 x 8W LED AC Integrated , 8W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE : Y
 CRI : 90 CRI
 COLOR_TEMP : 3000K
 LIGHTING_DIRECTION : Down

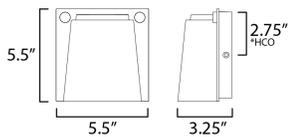

*Height from center of outlet to the top of the fixture

FINISHES OPTION

 Black / Antique Brass

MATERIAL

EPMM, Aluminum

RATINGS

cETLus
 Wet Location
 ADA



ADDITIONAL

INSTALL UP/DOWN: Down
 RATED LIFE 35000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com