




PRODUCT DESCRIPTION

Modeled on open weave wicker stitchwork and constructed using synthetic rattan for longevity, this series of wall sconces are rated for both interiors and outdoors. Matte Black frames are paired with either Natural Rattan or a matching Black finish. This homespun concept pays homage to the outdoors with relevant styling and timeless appeal.

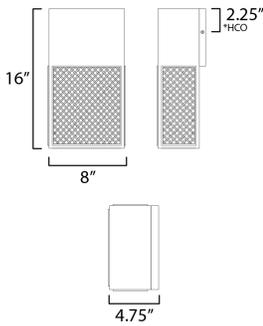

*Height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 8" W x 16" H x 4.75" Ext
 BACK PLATE : 6" W x 5" H x 2.25" HCO
 HANGING WEIGHT : 6.6 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 1,050 Rated (650 Del.)
 BULB : 1 x 15W LED AC Integrated , 15W Total
 BULB INCLUDED : (Integrated)
 CRI : 90 CRI
 COLOR_TEMP : 3000K
 LIGHTING_DIRECTION : Down

FINISHES OPTION

 Black

MATERIAL

Aluminum, Synthetic Rattan

RATINGS

cETLus
 Wet Location
 DARKSKY



ADDITIONAL

INSTALL UP/DOWN: Down
 RATED LIFE 35000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com