




PRODUCT DESCRIPTION

Inspired design for hospitality and residences, this collection features shades of white Wafer fabric and heavy Polished Chrome arms that characterize the quality of these products. Be it bedside or suspension the sweeping, swinging, and adjustable light sources allows you to direct the light to your preference. All products include LED lamping.

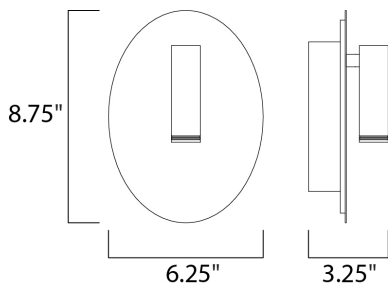

MEASUREMENTS

DIMENSION : 6.25" W x 10" H x 6" Ext
HANGING WEIGHT : 2.01 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 860 Rated
BULB : 2 x 15W LED PCB Integrated , 15W Total
BULB INCLUDED : (Integrated)
DIMMABLE : No
CRI : 80+ CRI
COLOR_TEMP : 3000K
LIGHTING_DIRECTION : Directional

FINISHES OPTION

 Black / Polished Chrome

MATERIAL

Steel, Acrylic

RATINGS

cETLus
Dry Location



ADDITIONAL

INSTALL UP/DOWN: Up/Down
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com