




PRODUCT DESCRIPTION

Inspired design for hospitality and residences, this collection features shades of white Wafer fabric and heavy Polished Chrome arms that characterize the quality of these products. Be it bedside or suspension the sweeping, swinging, and adjustable light sources allows you to direct the light to your preference. All products include LED lamping.

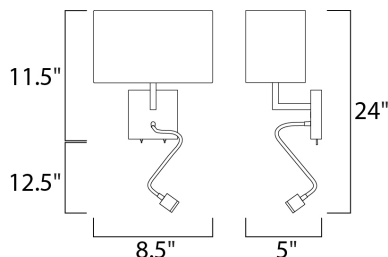

MEASUREMENTS

DIMENSION : 8.5" W x 24" H x 5" Ext
 MAX OAH : 11.5" H
 HANGING WEIGHT : 3.73 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 685 Rated
 BULB : 2 x 9W LED GU24 + PCB , 9W Total
 BULB INCLUDED : (Included)
 DIMMABLE : No
 CRI : 90+ CRI
 COLOR_TEMP : 3000K

FINISHES OPTION



MATERIAL

Steel, Fabric Shade

RATINGS

cETLus
 Dry Location



ADDITIONAL

INSTALL UP/DOWN: Up/Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com