




PRODUCT DESCRIPTION

Inspired design for hospitality and residences, this collection features shades of white Wafer fabric and heavy Polished Chrome arms that characterize the quality of these products. Be it bedside or suspension the sweeping, swinging, and adjustable light sources allows you to direct the light to your preference. All products include LED lamping.

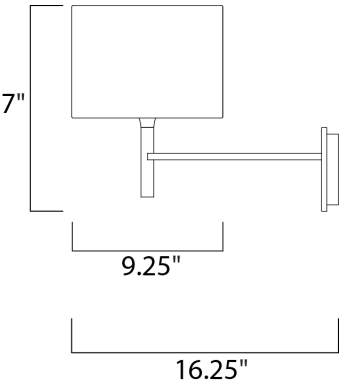

MEASUREMENTS

DIMENSION : 12.5" W x 17.25" H x 17" Ext
MAX OAH : 4.8" W
HANGING WEIGHT : 2.43 lb

LAMPING

INPUT VOLTAGE : 120V
LUMENS : 600 Rated
BULB : 1 x 9W LED GU24 , 9W Total
BULB INCLUDED : (Included)
DIMMABLE : Electronic Low Voltage (ELV)
CRI : 90+ CRI
COLOR_TEMP : 3000K

FINISHES OPTION

 Polished Chrome

MATERIAL

Steel, Fabric Shade, Zinc Alloy

RATINGS

cETLus
Dry Location
JA8 Bulb In



ADDITIONAL

INSTALL UP/DOWN: Up
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com