




**PRODUCT DESCRIPTION**

A transitional look that works in a broad range of interiors featuring metal frames finished in either Oiled Rubbed Bronze for the traditional home or Satin Nickel for a more contemporary look. Simple Frost glass shades compliment the overall design.

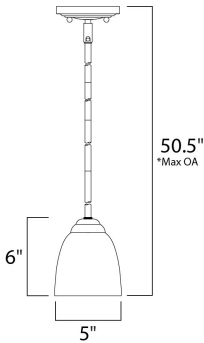

\*max overall height

**MEASUREMENTS**

DIMENSION : 5" L x 5" W x 6" H  
MAX OAH : 50.5" OAH  
HANGING WEIGHT : 2.49 lb

**LAMPING**

INPUT VOLTAGE : 120V  
BULB : 1 x 60W Incandescent E26 Medium , 60W Total  
BULB INCLUDED : (Not Included)  
DIMMABLE : Yes

**FINISHES OPTION**

- Black
- Oil Rubbed Bronze
- Satin Nickel

**GLASS**

Frosted FT

**MATERIAL**

Steel, Glass

**RATINGS**

cULus  
Dry Location



**ADDITIONAL**

ADJUSTABLE  
SLOPE: 120  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269  
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com