


MOTICAM Series

MOTICAM BTI10



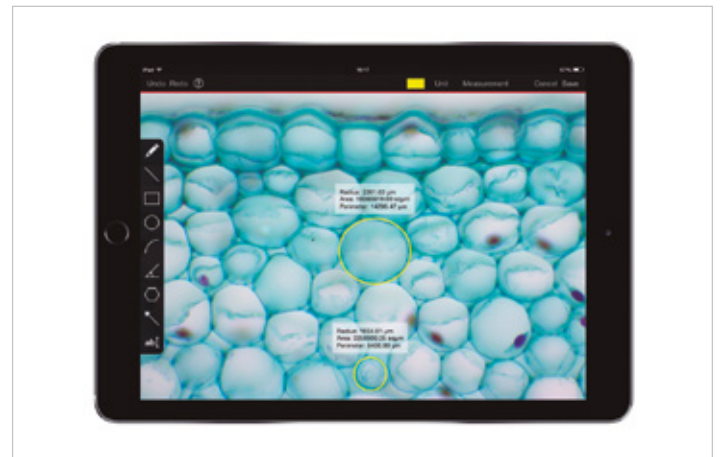

MOTICAM Series - Tablet Cameras

MOTICAM BTI10

Camera Specifications

Sensor type	CMOS
Sensor size	1/3"
Live resolution	1920x1080, 1280x720 (display resolution)
Image capture resolution	4.0MP
Video capture resolution	720P (HD)
Data transfer	Wi-Fi (2.4 or 5 GHz) and Ethernet (RJ45)
Pixel size	2.0µm x 2.0µm
Lens mount	C-Mount
Tablet bracket holder	For tablets from 7" to 10"

Tablet Specifications

Size	218x136x910mm
System	Android 10
Pre-installed App	MotiConnect
Language	Multi-Language
CPU	2.0GHz 8-core
RAM	6GB DDR3
NAND FLASH	128GB
Display	1920x1200
Ports	MicroSD/MMC/TF Card (Support up 64 GB), 3.5mm Audio, USB-C (USB OTG and Charging)
Support display format	MPEG-1/2 (DAT, MPG, VOB, TS), MPEG-4, H.263 (3GP, MOV, MP4), H.264 (AVI, MKV, MP4, MOV, 3GP), RM, RMVB, FLV, WEBM
Support audio format	MP3, WMA, MP2, OGG, AAC, M4A, OGA, FLAC, APE, MP1, WAV
Picture format	JPEG, GIF, BMP, PNG
Camera	Front (5M Pixels) + Rear (8M Pixels)
Package includes	USB Cable, Motic 4-dot calibration slide, universal power supply 100V-240V (CE)