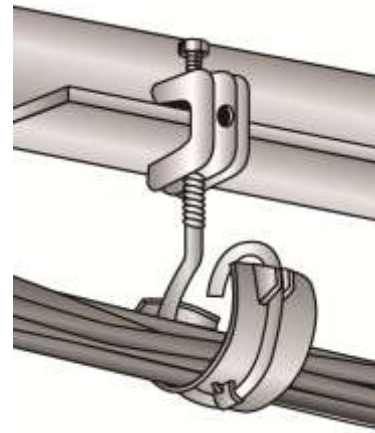


Part Number: BR-2.0-1/4-20S

Product Description: BRIDLE RING WITH SADDLE - 2" CAPACITY - MOUNTS WITH 1/4-20 THREADS

**Material Specifications**

Type: Assembly

Color: Various

Finish: Assembly

Function Specifications**Compatible Wires and Cables**

AC/MC CABLE (OD):

Drop Wire:

Plain Rod (in):

Threaded Rods and Bolts

Tapped Holes:

Clearance Holes (in):

Threaded Rod Size (in): 1/4"-20

Compatible Conduit

EMT Size (in):

Rigid/IMC (in):

Compatible Flanges and Studs

Flange Size (in):

Metal Stud Size (ins):

Static Load Rating

Vertical (lbs):

Horizontal (lbs):

Other

2" bridle ring with saddle

--

Codes and RegulatoryRegulatory
Certifications: UL/CUL

Country of Origin: US

--

--

Packaging

General Packaging: Cardboard Box

Box Size: 11 X 7.5 X 7.25

Pieces per Package: 50

Other Box Features:

Document Information

Created By: DBLA

Checked By: DJW

Approved By: KLN

Customer Specification #: C11445

Revision Level: 0

ECN #: GAECN01813

Date: 3/19/2014

