



# AIR CONDITIONER

## 10,000 BTU WINDOW AC



**FOLLOW ME**  
Portable remote control thermostat feature for total room coverage


### WINDOW AC FEATURES

- Electronic controls
- Full range air direction control
- Temperature output range of 62°F–86°F (17°C–30°C)
- Auto, Sleep, Dry & Energy Saver modes
- Full function remote control
- 24 hour timer
- Window mounting kit
- Auto restart function
- Tilt-out filter access

### CHOOSING

THE RIGHT SIZE AIR CONDITIONER FOR YOUR ROOM


#### 1 MEASURE AREA OF THE ROOM

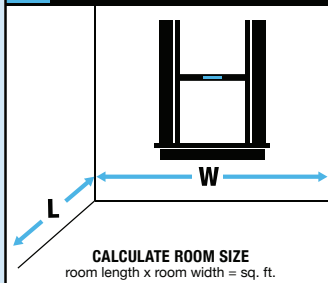

#### 2 MATCH ROOM SIZE WITH CORRECT BTUs


ROOM SIZE (sq. ft.)	BTUs	
150	10' x 15'	5,000
250	15.5' x 16'	6,000
350	17.5' x 20'	8,000
450	18' x 25'	10,000
550	22' x 25'	12,000
700	25' x 28'	15,000
1,000	31.25' x 32'	18,000
1,500	37.5' x 40'	25,000
2,000	40' x 50'	28,500

#### 3 CONFIRM WINDOW OPENING SIZE

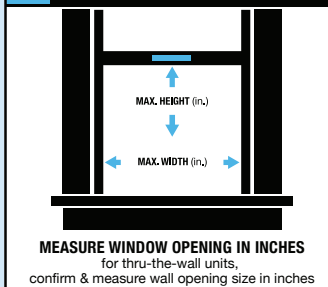

#### 4 CHECK ELECTRICAL REQUIREMENTS

##### OUTLET CONFIGURATIONS

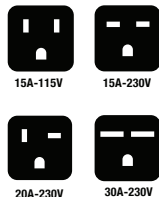

**DETERMINE IF YOUR CIRCUIT IS ADEQUATE**

4PNC10000	
<b>UPC CODE</b>	8-42149-02537-3
<b>COOLING CAPACITY (BTU)</b>	10,000
<b>COVERAGE (sq. ft.)</b>	400–450
<b>EER</b>	10.9
<b>ENERGY STAR RATED</b>	No
<b>FAN SPEEDS (Cool/Fan)</b>	3/3
<b>AMPS</b>	8.0
<b>WATTS</b>	905
<b>DECIBELS (Hi/Mi/Lo)</b>	59/55/53
<b>WINDOW WIDTH (Min./Max.) (in.)</b>	23/36
<b>WINDOW HEIGHT (Min.) (in.)</b>	15 <sup>1/2</sup>
<b>UNIT DIMENSIONS (WxHxD) (in.)</b>	19 x 14 <sup>3/4</sup> x 21 <sup>1/2</sup>
<b>PKG. DIMENSIONS (WxHxD) (in.)</b>	22 x 17 x 23 <sup>1/4</sup>
<b>STUFFING QTY. (20'/40'/40' HQ)</b>	190/410/498
<b>WEIGHT (Net/Gross) (lbs.)</b>	60/68
<b>REFRIGERATION</b>	R32
<b>OUTLET CONFIGURATION</b>	15 AMP 115V



PA/SS\_4PNC10000/11202018

5401 Dansher Road  
Countryside, IL 60525

866.996.9255  
630.323.2301

www.perfectaire.us  
support@perfectaire.us