

# 3-4079D

## Wall Mount, Outdoor

### Features

#### Housing

Die-cast Aluminum with Powder Coated Finish  
Finish Options: -05 Black, -30 Oil Rubbed Bronze, -08 Gray  
Good for Wet Location Applications

#### Optical

Shade: Frosted Glass

#### Electrical

120V -277  
High Power Factor, Low THD

#### Lamp


Integrated LED Module, Color Temperature Option 3000K or 4000K

#### Certification

ETL/cETL Listed, Suitable for Wet Locations

#### Warranty

5 Years Limited Warranty on Driver and LED

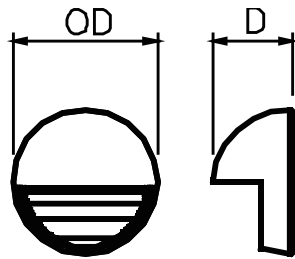

### LED Type

Model	Input Voltage	Input Wattage	LED CT	Lumen (TYP)	Finish	Shade	Dimension (OD X E)
3-4079D-05-xxxxK	120V -277V	9W	3000K or 4000K	390	Black	Frosted Glass	6.3" x 3.4"