

# 4479-A

## Mini Pendant

### Features

#### Housing

Cold-rolled Steel

Finish Option: -62 Satin Nickel -30 Oil Rubbed Bronze

#### Optical

Shade: Clear Glass

#### Electrical


120V

#### Lamp

E26 Filament Type LED Bulb: 8W, Energy Star Listed, Dimmable, Omini Direction Type, Color Temperature 2700K

#### Certification

UL/cUL Listed

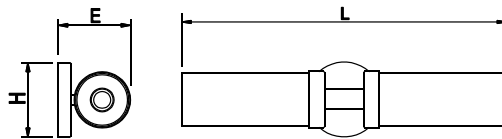

### CFL Type

Model	Input Voltage	Finish	Shade	Dimension (L x E x H)	Lamp	Energy Star
4479-A-62	120V	Satin Nickel	Clear Glass	20.0" x 4.7" x 4.5"	E26 Filament Type LED Bulb, 8W, 2700K	---
4479-A-30	120V	ORB	Clear Glass	20.0" x 4.7" x 4.5"	E26 Filament Type LED Bulb, 8W, 2700K	---