

6610D

Vanity

Features

Housing

Die-formed Cold-rolled Steel

Finish Option: -62 Satin Nickel, -30 Oil Rubbed Bronze

Optical

Opal Glass with Clear Glass Shade Creates Excellent Light Distribution and Uniformity

Electrical

High Power Factor, Low THD

Lamp


LED Bulb: E26, 9W, 3000K or 4000K

Certification

UL/cUL

Warranty

LED E26 Bulb: 3 Years Limited Warranty

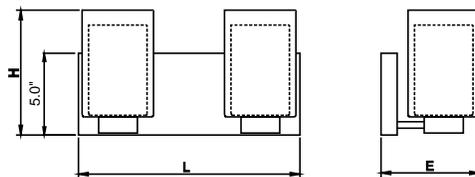

LED Type

Model	Input Voltage	Input Wattage	Lumen (TYP)	Finish	Lamp	Dimension (L X H X E)
6610D-109	120V	9W	800	Satin Nickel	1 x 9W E26	5.0" x 7.5" x 6.0"
6610D-209	120V	18W	1600	Satin Nickel	2 x 9W E26	13.5" x 7.5" x 6.0"
6610D-309	120V	27W	2400	Satin Nickel	3 x 9W E26	22.0" x 7.5" x 6.0"