

# FL0224D-VT FL0239D-VT FL0254D-VT

## Vanity

### Features

#### Housing

Aluminum Extrusion with Die-Form Cold-Rolled Steel Ends  
 Finish Option: -62 Satin Nickel -30 Oil Rubbed Bronze

#### Optical

Shade: High Transmission Acrylic Create Excellent Light Distribution and Uniformity  
 LED: High Efficiency, High CRI, Binned and Mixed to Reach Uniform Light.

#### Electrical

High Power Factor, Low THD

#### Lamp


LED Type: Built-in (Color Temperature Option – 3000K, 3500K, 4000K, 5000K)

#### Certification

ETL/cETL Listed for Damp Locations, Energy Star

#### Warranty

5 Years Warranty on Driver and LED Module

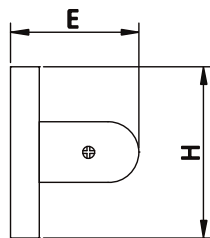

### LED Type

Model	Input Voltage	Input Wattage	LED CT / CRI	Lumen (TYP)	Finish	Dimension (L x Hx E)	Energy Star
FL0224D-VT-xxxxK	120V ~ 277V	11W	3000K / >80	935	Satin Nickel	22.0" x 4.8" x 3.8"	Yes
FL0239D-VT-xxxxK	120V ~ 277V	18W	3000K / >80	1530	Satin Nickel	34.0" x 4.8" x 3.8"	Yes
FL0254D-VT-xxxxK	120V ~ 277V	23W	3000K / >80	1950	Satin Nickel	46.0" x 4.8" x 3.8"	Yes