

# FL5324 FL5339 FL5354

## Vanity

### Features

#### Housing

Die-formed Cold-rolled Steel

Finish Option: -62 Satin Nickel -30 Oil Rubbed Bronze

#### Optical

Shade: High Transmission Acrylic Create Excellent Light Distribution and Uniformity

LED: High Efficiency, High CRI, Binned and Mixed to Reach Uniform Light.

#### Electrical

High Power Factor, Low THD

#### Lamp

LED Type: Built-in (Color Temperature Option – 3500K, 4000K, 5000K)

MCT Type: Built-in (Multiple Color Temperature, Adjustable – 3000K, 3500K, 4000K)


Fluorescent Type: T5 HO Lamp

#### Certification

UL/cUL, ETL/cETL Listed, Damp Rated, Energy Star

#### Warranty

5 Years Warranty on Driver and LED Module

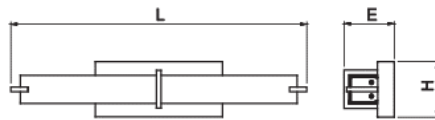

### LED Type

Model	Input Voltage	Input Wattage	LED CT / CRI	Lumen (TYP)	Finish	Dimension (L x H x E)	Energy Star
FL5324D-xxxxK	120V ~ 277V	17W	3000K / 80	1450	Satin Nickel	25.5" x 4.8" x 4.3"	Yes
FL5339D-xxxxK	120V ~ 277V	23W	3000K / 80	2000	Satin Nickel	37.5" x 4.8" x 4.3"	Yes
FL5354D-xxxxK	120V ~ 277V	35W	3000K / 80	3040	Satin Nickel	49.3" x 4.8" x 4.3"	Yes
FL5324D-MCT	120V ~ 277V	17W	3000K / 80	1450	Satin Nickel	25.5" x 4.8" x 4.3"	Yes
FL5339D-MCT	120V ~ 277V	23W	3000K / 80	2000	Satin Nickel	37.5" x 4.8" x 4.3"	Yes
FL5354D-MCT	120V ~ 277V	35W	3000K / 80	3040	Satin Nickel	49.3" x 4.8" x 4.3"	Yes

### LED Type, High Lumen

Model	Input Voltage	Input Wattage	LED CT	CRI	Lumen (TYP)	Finish	Dimension (L x H x E)	Energy Star
FL5324D-HO-62	120V ~ 277V	25W	3000K or 4000K	80	2000	Satin Nickel	25.5" x 4.8" x 4.3"	---
FL5339D-HO-62	120V ~ 277V	31W	3000K or 4000K	80	2580	Satin Nickel	37.5" x 4.8" x 4.3"	---

### T5 HO Lamp Type

Model	Input Voltage	Input Wattage	Finish	Shade	Lamp	Dimension (L x H x E)
FL5324	120V ~ 277V	24W	Satin Nickel	Acrylic	1 x F24T5HO, 24W	25.5" x 4.8" x 4.3"
FL5339	120V ~ 277V	39W	Satin Nickel	Acrylic	1 x F39T5HO, 39W	37.5" x 4.8" x 4.3"
FL5354	120V ~ 277V	54W	Satin Nickel	Acrylic	1 x F54T5HO, 54W	49.3" x 4.8" x 4.3"

**FL5324 FL5339 FL5354**

Vanity