

# FL5524D-A FL5539D-A FL5554D-A

## Vanity

### Features

#### Housing

Die-formed Cold-rolled Steel

Finish Option: -62 Satin Nickel -30 Oil Rubbed Bronze

#### Optical

Shade: High Transmission Acrylic Create Excellent Light Distribution and Uniformity

LED: High Efficiency, High CRI, Binned and Mixed to Reach Uniform Light.

#### Electrical

High Power Factor, Low THD

#### Lamp

LED Type: Built-in (Color Temperature Option – 3000K, 3500K, 4000K, 5000K)


MCT Type: Adjustable Multiple Color Temperature (3000K, 3500K, 4000K)

#### Certification

ETL/cETL Listed

#### Warranty

5 Years Warranty on Driver and LED Module

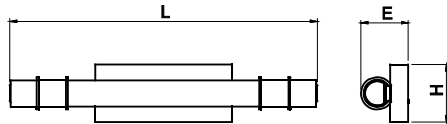

### LED Type

Model	Input Voltage	Input Wattage	LED CT / CRI	Lumen (TYP)	Finish	Dimension (L x H x E)	Energy Star
FL5524D-xxxxK-A	120V	17W	3000K / 80	1520	Satin Nickel	24.8" x 4.7" x 3.5"	Yes
FL5524D-HO-xxxxK-A	120V ~ 277V	25W	3000K / 80	2000	Satin Nickel	24.8" x 4.7" x 3.5"	---
FL5539D-xxxxK-A	120V ~ 277V	23W	3000K / 80	2110	Satin Nickel	36.8" x 4.7" x 3.5"	Yes
FL5539D-HO-xxxxK-A	120V ~ 277V	31W	3000K / 80	2580	Satin Nickel	36.8" x 4.7" x 3.5"	---
FL5554D-xxxxK-A	120V ~ 277V	36W	3000K / 80	3220	Satin Nickel	48.5" x 4.7" x 3.5"	Yes
FL5524D-A-MCT	120V ~ 277V	17W	3000K / 80	1520	Satin Nickel	24.8" x 4.7" x 3.5"	Yes
FL5539D-A-MCT	120V ~ 277V	23W	3000K / 80	2110	Satin Nickel	36.8" x 4.7" x 3.5"	Yes
FL5554D-A-MCT	120V ~ 277V	36W	3000K / 80	3220	Satin Nickel	48.5" x 4.7" x 3.5"	Yes