

# P058-3

## Mini Pendant

### Features

#### Housing

Cold-rolled Steel

Finish Option: -62 Satin Nickel -30 Oil Rubbed Bronze

#### Optical

Shade: Opal Glass

#### Electrical


120V

#### Lamp

E26 LED Bulb: 9W, Energy Star Listed, Dimmable, Omini Direction Type, Color Temperature, 3000K, 4000K

#### Certification

UL/cUL Listed

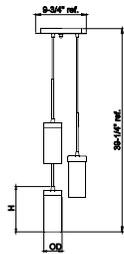

### CFL Type

Model	Input Voltage	Finish	Shade	Dimension (OD x H x H1)	Lamp	Energy Star
P058-3-62	120V	Satin Nickel	Opal Glass	3.5" x 8.5" x 6.0'	9W E26 LED Bulb	---

Note: H1- Hanging Cable Length