

P201D

LED Mini Pendant

Features

Housing

Aluminum with Black Finish

Optical

Shade: Golden

Electrical

120V

Lamp


GU24 LED Bulb: 9W, Energy Star Listed, Dimmable, Omni Direction Type, Color

Temperature Option – 3000K, 4000K

GU24 CFL Bulb: 13W, 2700K or 4000K

Certification

ETL/cETL Listed

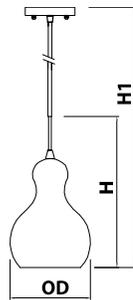

LED Type, Dimmable

Model	Input Voltage	Lamp	LED CT / CRI	Lumen (TYP)	Dimension (OD x H x H1 max)	Finish
P201D-05-3000K	120V	13W CFL or 9W GU24 LED Bulb	3000K / >80	820	8.9" x 12.0" x 6.0'	Black

Note: H1- Hanging Cable Length