

# P207D

## LED Mini Pendant

### Features

#### Housing

Aluminum with Brush Finish

#### Optical

#### Electrical

120V


#### Lamp

GU24 LED Bulb: 9W, Energy Star Listed, Dimmable, Omni Direction Type, Color Temperature Option – 3000K, 4000K

GU24 CFL Bulb: 13W, 2700K or 4000K

#### Certification

ETL/cETL Listed

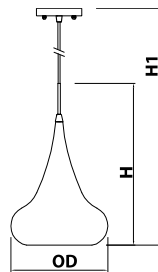

### LED Type, Dimmable

Model	Input Voltage	Lamp	LED CT / CRI	Lumen (TYP)	Dimension (OD x H xH1 max)	Finish
P207D-60-3000K	120V	13W CFL or 9W GU24 LED Bulb	3000K / >80	820	11.8" x 15.0" x 6.0'	Brush Aluminum

Note: H1- Hanging Cable Length