

P209D

LED Mini Pendant

Features

Housing

Die-formed Cold-rolled Steel
Metal Reflector
Canopy Size: 4.8" OD x 1.0" H

Electrical


120V, 9W

Lamp

LED Bulb: 9W, A19, Energy Star Listed, Dimmable, Omni Direction Type
Color Temperature Option: 3000K or 4000K

Certification

ETL/cETL Listed

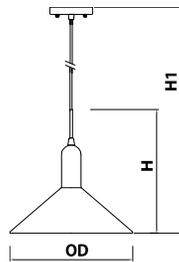

LED Type, Dimmable

Model	Input Voltage	LED Lamp	LED CT	Lamp Lumen (TYP)	Finish	Shade	Dimension (OD x H x H1 max)
P209D-05/22-E26	120V	9W, A19	3000K or 4000K	800	Black / Gold	Metal Reflector	13.8" x 10.8" x 6.0'

Note: H1- Hanging Cable Length, Adjustable